




MULTILAYER CERAMIC CHIP

HIGH FREQUENCY RF & MICROWAVE CAPACITORS


VJ HIFREQ SERIES
25 V to 250 V, up to 1500 pF

QUAD HIFREQ SERIES
50 to 7200 V, Up to 12 nF

VISHAY QUAD CAPACITORS
HANDLE 35 % MORE POWER

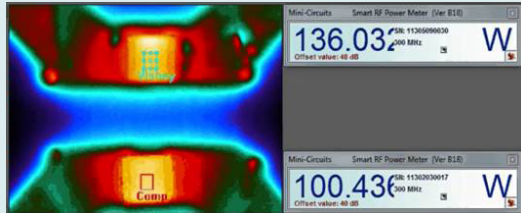


HIGH TEMPERATURE OPERATION

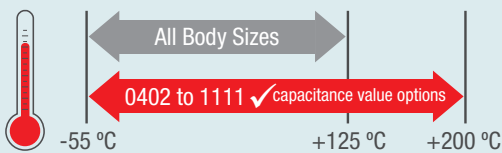

TERMINATION OPTIONS

- Lead (Pb)-free, RoHS-compliant: "X"
- Tin / lead (min. 4 % Pb): "L"
- Non-magnetic copper: "C"

www.vishay.com

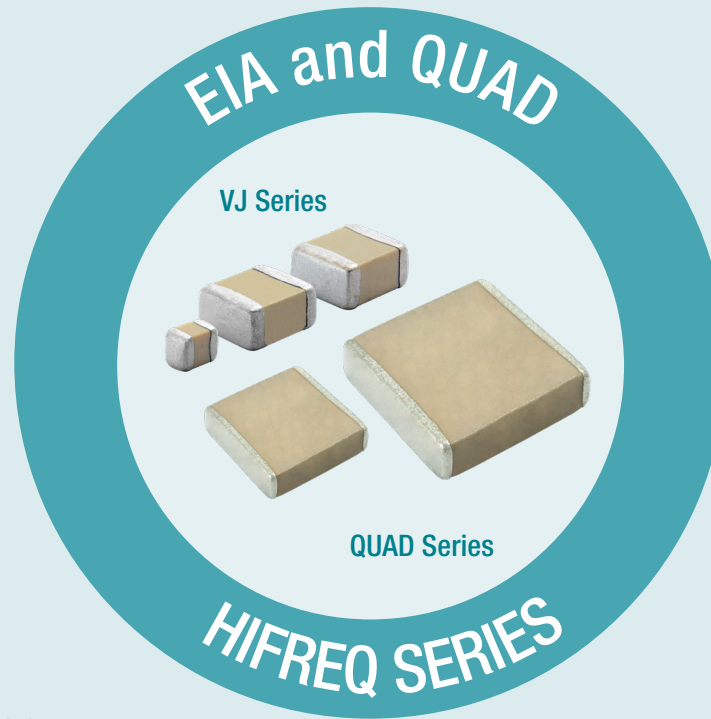

SMD MLCCS FOR RF & MICROWAVE APPLICATIONS

High Q, Ultra Low ESR,
Stable COG (NPO) Dielectric

MORE EFFICIENT



Power Delivery
for RF Amplifiers

APPLICATIONS



MILITARY RADIOS



WIRELESS POWER



INSTRUMENTATION



5G NETWORKS

FOOTPRINT
Actual size shown

