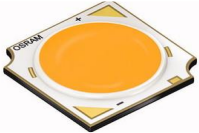

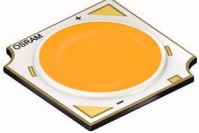

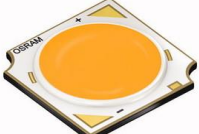

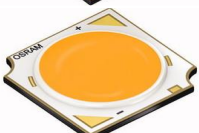

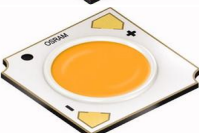

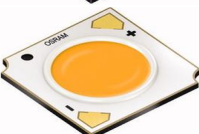

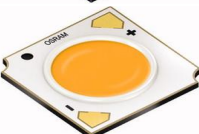



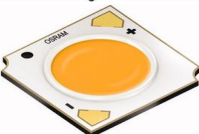

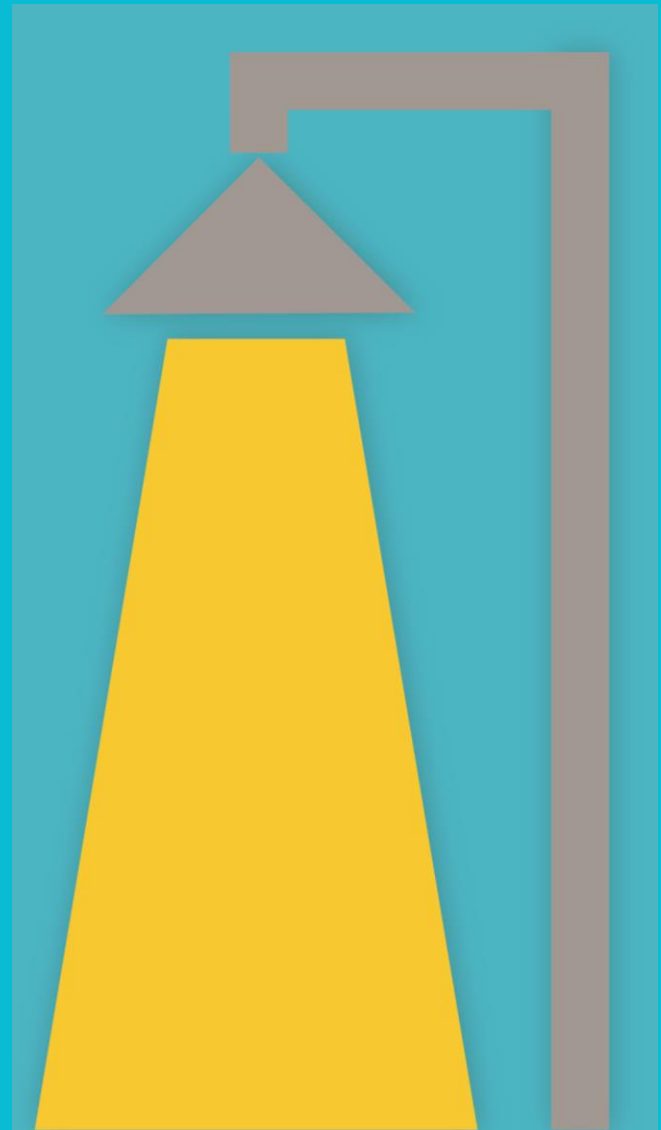
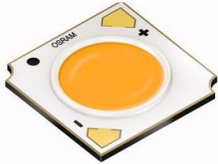
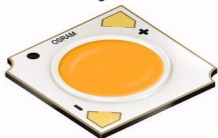





# OSRAM-AIMTEC SELECTOR GUIDE



OSRAM COB Image	OSRAM Model	Forward Current	Forward Voltage	Power	Aimtec LED Driver	
	GW KAFGB3.CM	460 Ma	34.7	16	AMEPR30-4250Z AMEPR30N-4250Z AMEPR30NC-4250Z	
	GW KAFHB3.CM	690mA	34.7	24	AMEPR30-4270Z AMEPR30N-4270Z AMEPR30NC-4270Z	
	GW KAFJB3.CM	920mA	34.7	32	AMEPR40-42100Z AMEPR40N-42100Z AMEPR40N-42100Z-P AMEPR40NC-42100Z AMEPR40NC-42100Z-P	
	GW KAGHB1.EM	720mA	32	23	AMEPR30-4270Z AMEPR30N-4270Z AMEPR30NC-4270Z	
	GW KAGHB2.EM	700mA	35	25	AMEPR30-4270Z AMEPR30N-4270Z AMEPR30NC-4270Z	
	GW KAGJB2.EM	1200mA	35	42	AMEPR50N-42115Z AMER50-42120Z AMER50N-42120Z	
	GW KAGLB2.EM	1400mA	35	49	AMER60-42140Z AMER60N-42140Z	
	GW KAGHB2.CM	700mA	35	25	AMEPR30-4270Z AMEPR30N-4270Z AMEPR30NC-4270Z	
	GW KAGGB3.CM	460mA	34.7	16	AMEPR30-4250Z AMEPR30N-4250Z AMEPR30NC-4250Z	



OSRAM COB Image	OSRAM Model	Forward Current	Forward Voltage	Power	Aimtec LED Driver
	GW KAGJB3.CM	1150	34.7	40	AMEPR50N-42115Z AMER50-42120Z AMER50N-42120Z
	GW KAGLB3.CM	1380	34.7	48	AMER60-42140Z AMER60N-42140Z
	GW KAGMB3.CM	1610	34.7	56	AMER60-42160Z AMER60N-42160Z
	GW KAHNB1.EM	1400	43.2	61	AMER70N-50170Z
	GW KAHLB1.EM	1000	46.5	56.5	AMEQR50N-50100Z
	GW KAHLB2.CM	1920	34.8	67	AMER90-42200Z
	GWKAHLB2.DM	1920	36.5	70	AMER90-42200Z
	GW KAHQB2.EM	2530	36	91	AMER120-42250Z AMER130-55240Z
	GW KAGHB3.CM	690mA	34.7	24	AMEPR30-4270Z AMEPR30N-4270Z AMEPR30NC-4270Z

