



CX70M Series

Minimized Size Mid-mount USB Type-C Connector






◆ Features

1. USB3.1 Gen1 (5Gbps), high speed transmission
2. USB Type-C compliant interface connector
3. Minimized length design for space saving
4. Reversible plug insertion
5. Hybrid mounting design provides easy inspection and rework
6. RoHS compliant, Halogen free product*

* This product satisfies halogen free requirements defined as 900ppm maximum chlorine, 900ppm maximum bromine and 1500ppm maximum total of chlorine and bromine.

◆ Mid-mount & minimized length design

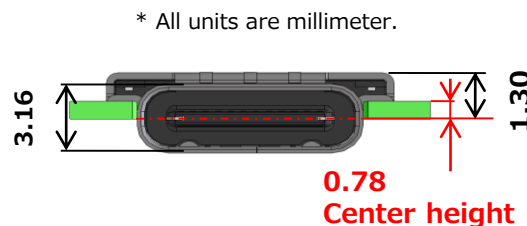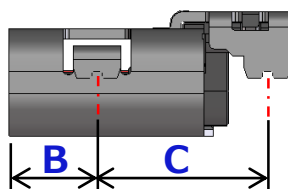
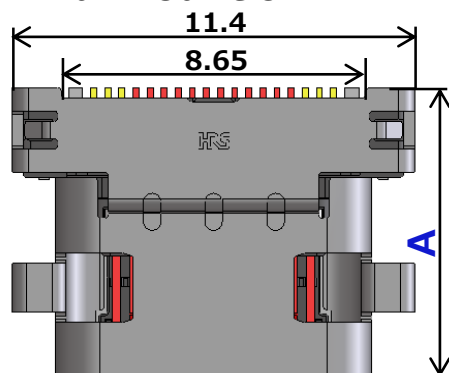


* All units are millimeter.


Part NO	Dimensions		
	A	B	C
CX70M-24P1 (TID5200000077)	8.35	2.6	5.05
CX70M-24P2 (TID: None)	7.95	2.2	5.05

◆ Supporting repair availability


- Top view (SMT)
- Bottom view (DIP)

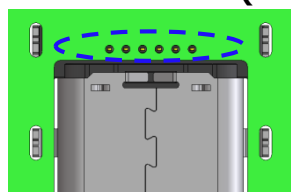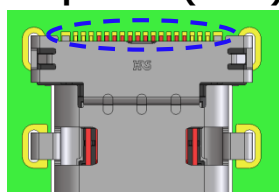

■ Bottom view without PCB

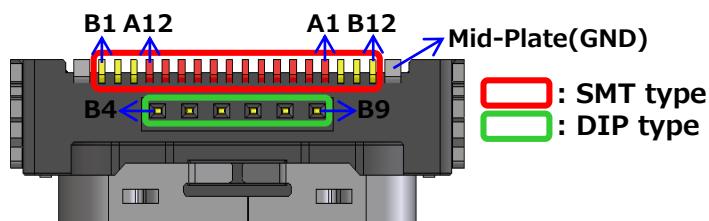

◆ Reversible plug inserting

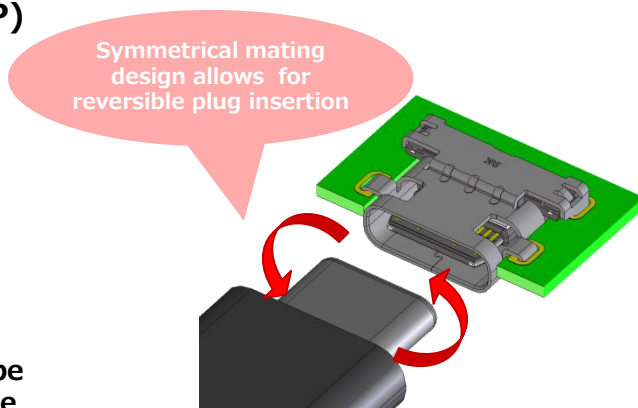

⇨ Reversible plug insertion

⇨ CX70M is Hybrid(SMT + DIP) mounting type

※Specifications herein are subject to change without notice. Contact Hirose for latest specifications, drawings or availabilities.

Jun.1.2017 Copyright 2017 HIROSE ELECTRIC CO., LTD. All Rights Reserved.